

VL3N Female Quick Disconnect No-Spill Coupling, Panel Barb for ID 10mm (3/8in)




Koolance patented quick disconnect no-spill coupling with automatic shutoff. 10mm (3/8in) ID female panel-mountable barb fitting with spring clamp. It will only fit a Koolance VL3N male quick disconnect.

After a quarter twist, the quick-disconnect fittings will separate. Liquid on both sides will be automatically obstructed with approximately 0.2ml freed. Coolant volume lost upon disconnection will rise with internal pressure higher than 0.5kgf/cm² (7psi). Maximum operating pressure is 2-2.5kgf/cm² (28-35 psi). Maximum operating temperature is 90 °C.

General	
Weight	0.17 lb (0.08 kg)

Koolance "VL3N" 10mm ID Panel Barb Hole Size

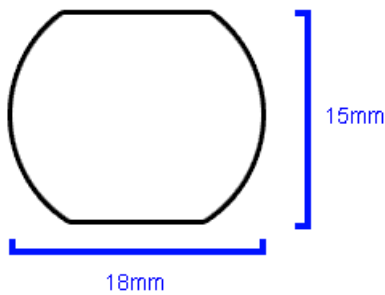

No-Spill Shut-Off Valve

