

VL3N Female Quick Disconnect No-Spill Coupling, Threaded G 1/4 BSPP




Koolance patented quick disconnect no-spill coupling with automatic shutoff. G 1/4 BSPP (parallel) thread female fitting for screwing directly into a water block or other component. It will only fit a Koolance VL3N male quick disconnect.

After a quarter twist, the quick-disconnect fittings will separate. Liquid on both sides will be automatically obstructed with approximately 0.2ml freed. Coolant volume lost upon disconnection will rise with internal pressure higher than 0.5kgf/cm² (7psi). Maximum operating pressure is 2-2.5kgf/cm² (28-35 psi). Maximum operating temperature is 90 °C.

General

Weight	0.14 lb (0.06 kg)
--------	-------------------

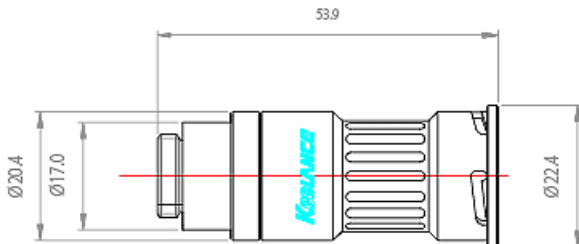

No-Spill Shut-Off Valve

