

**VL3N Male Quick Disconnect No-Spill  
Coupling, for 13mm x 19mm (1/2in x 3/4in)**




Koolance patented quick disconnect no-spill coupling with automatic shutoff. 13mm (1/2in) ID, 19mm (3/4in) OD male straight connection with compression fitting. It will only fit a Koolance VL3N female quick disconnect.

After a quarter twist, the quick-disconnect no-spill fittings will separate. Liquid on both sides will be automatically obstructed with approximately 0.2ml freed. Coolant volume lost upon disconnection will rise with internal pressure higher than 0.5kgf/cm<sup>2</sup> (7psi). Maximum operating pressure is 6kgf/cm<sup>2</sup> (85 psi). Maximum operating temperature is 90°C.

**General**

Weight	0.14 lb (0.06 kg)
--------	-------------------

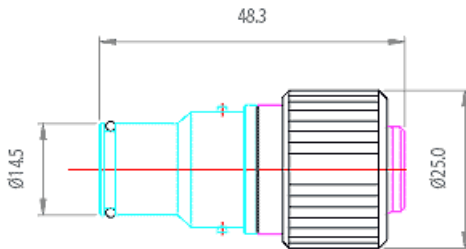

No-Spill Shut-Off Valve

