


VL3N Male Quick Disconnect No-Spill Coupling, Panel Barb for ID 13mm (1/2in)




Koolance patented quick disconnect no-spill coupling with automatic shutoff. 13mm (1/2in) ID male panel-mountable barb fitting with spring clamp. It will only fit a Koolance VL3N female quick disconnect.

After a quarter twist, the quick-disconnect fittings will separate. Liquid on both sides will be automatically obstructed with approximately 0.2ml freed. Coolant volume lost upon disconnection will rise with internal pressure higher than 0.5kgf/cm² (7psi). Maximum operating pressure is 6kgf/cm² (85 psi). Maximum operating temperature is 90°C.

General	
Weight	0.10 lb (0.05 kg)

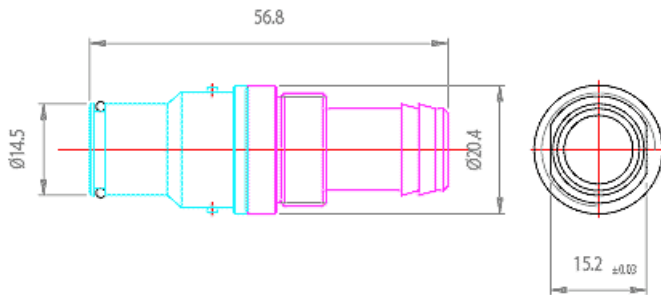

Koolance "VL3N" ID Panel Barb Hole Size

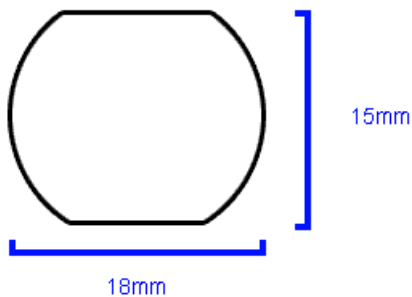

No-Spill Shut-Off Valve

