

## VL3N Male Quick Disconnect No-Spill Coupling, Threaded G 1/4 BSPP




Koolance patented quick disconnect no-spill coupling with automatic shutoff. G 1/4 BSPP (parallel) thread male fitting for screwing directly into a water block or other component. It will only fit a Koolance VL3N female quick disconnect.

After a quarter twist, the quick-disconnect fittings will separate. Liquid on both sides will be automatically obstructed with approximately 0.2ml freed. Coolant volume lost upon disconnection will rise with internal pressure higher than 0.5kgf/cm<sup>2</sup> (7psi). Maximum operating pressure is 6kgf/cm<sup>2</sup> (85 psi). Maximum operating temperature is 90°C.

### General

Weight	0.08 lb (0.04 kg)
--------	-------------------

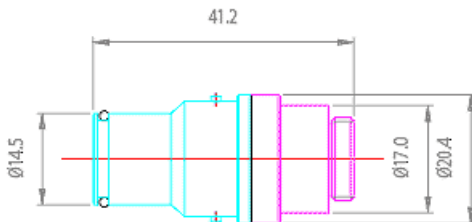

No-Spill Shut-Off Valve

