


## VL4N Male Quick Disconnect No-Spill Coupling, Threaded G 3/8 BSPP



Koolance patented quick disconnect no-spill coupling with automatic shutoff. G 3/8 BSPP (parallel) thread male fitting for screwing directly into a water block or other component of same threading. It will only fit a Koolance VL4N female quick disconnect.

After a quarter twist, the quick-disconnect fittings will separate. Liquid on both sides will be automatically obstructed with approximately 0.2ml freed. Coolant volume lost upon disconnection will rise with internal pressure higher than 0.5kgf/cm<sup>2</sup> (7psi). Maximum operating pressure is 5kgf/cm<sup>2</sup> (71 psi). Maximum operating temperature is 90°C.

| General |                   |
|---------|-------------------|
| Weight  | 0.14 lb (0.06 kg) |

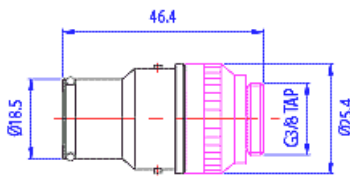

No-Spill Shut-Off Valve

