



**P/N: SPL-YF2MS1G4-BK****Y-Splitter, Dual Female, Single Swivel Male G  
1/4 BSPP, \*Black\***

Koolance "Y-shape" tubing splitter with one swiveling male and two female G 1/4 BSPP threads. Made of brass with EPDM o-rings.

General	
Weight	0.10 lb (0.05 kg)
Fitting Thread	G 1/4 BSPP
Max Pressure Tolerance @ 25°C	8kgf/cm2 (113.8psi)
Max Temperature Tolerance	120°C (248°F)

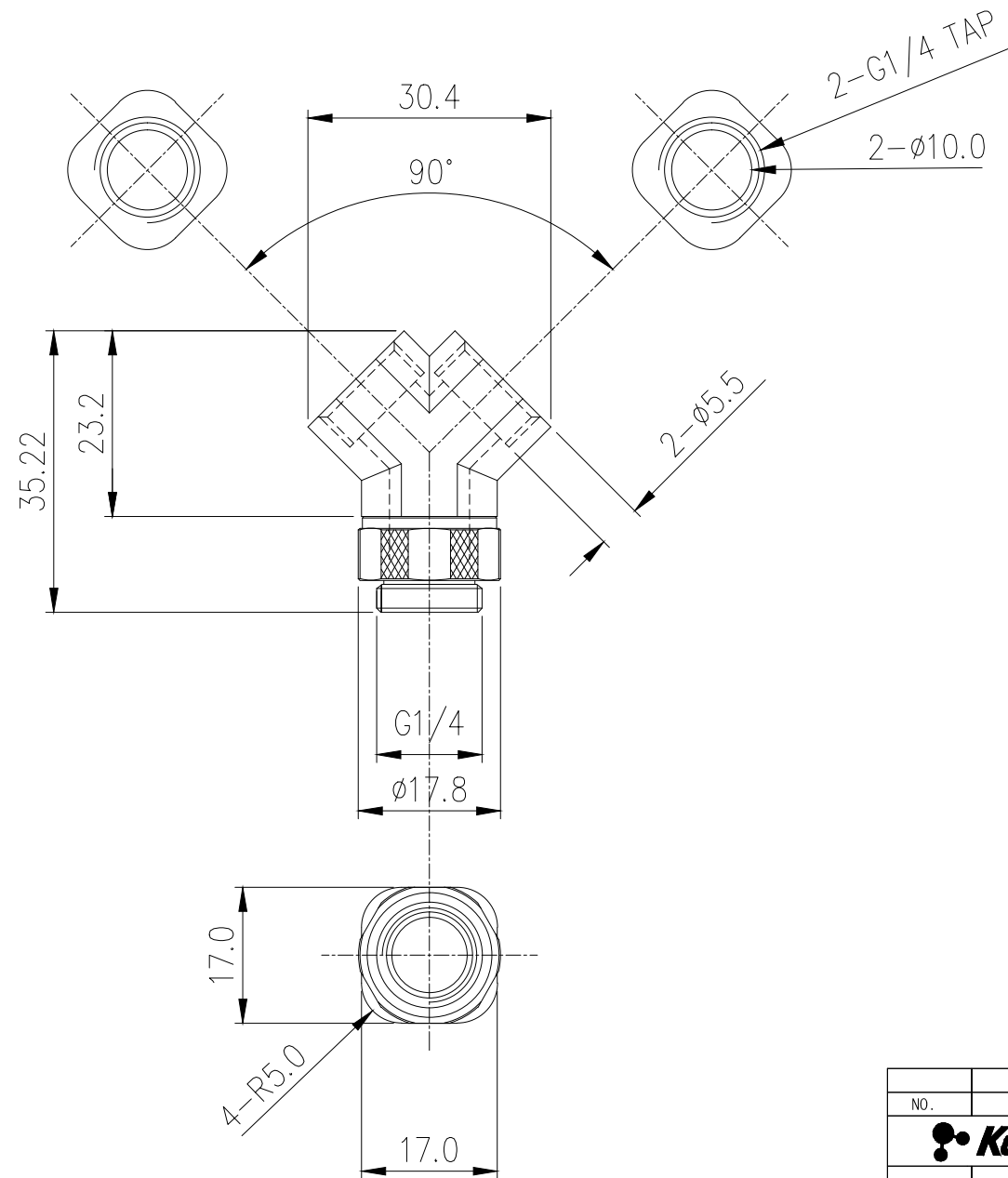

NO.		DESCRIPTION			MATER'L		QUANTITY		REMARKS		
 <b>KOOLANCE®</b>					UNIT	MM	APPAR   SPL—YF2MS1G4				
					SCALE	N/S	TITLE				
DATE		BY	BY	BY	APPRO	BY	Ass'y				
JAN.14.2021		S.J.LEE					CODE NO.		DWG. NO.		