



www.koolance.com

Specifications Sheet

Generated: 2024-04-24


P/N: SPL-YF3G4-BK


Y-Splitter, Triple Female G 1/4 BSPP, \*Black\*



Koolance "Y-shape" tubing splitter with three female G 1/4 BSPP threads. Made of brass.

General	
Weight	0.10 lb (0.05 kg)
Fitting Thread	G 1/4 BSPP
Max Pressure Tolerance @ 25° C	15kgf/cm2 (213.4psi)
Max Temperature Tolerance	120° C (248° F)

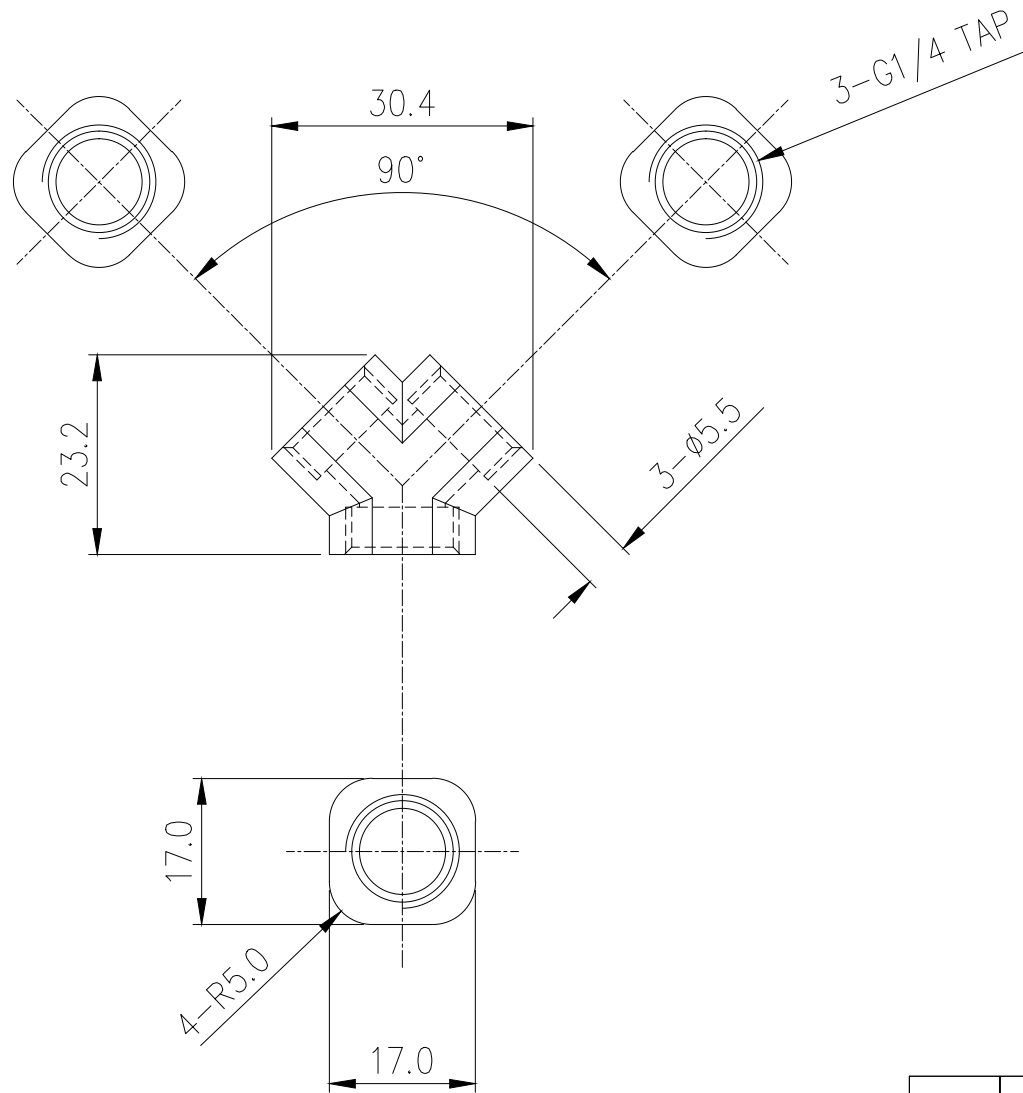

NO.		DESCRIPTION			MATER'L		QUANTITY		REMARKS	
 <b>KOOLANCE®</b>					UNIT	MM	APPAR      SPL – YF3G4			
					SCALE	N/S	TITLE			
DATE		BY	BY	BY	APPRO	BY	Ass'y			
JAN.14.2021		S.J.LEE					CODE NO.		DWG. NO.	